

M12 male 0° / M12 female 0° shielded

PUR 5x0.34 shielded gy UL/CSA 1m

Male straight – female straight

M12 – M12, 5-pole


A-coded

shielded

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

Further cable lengths on request.

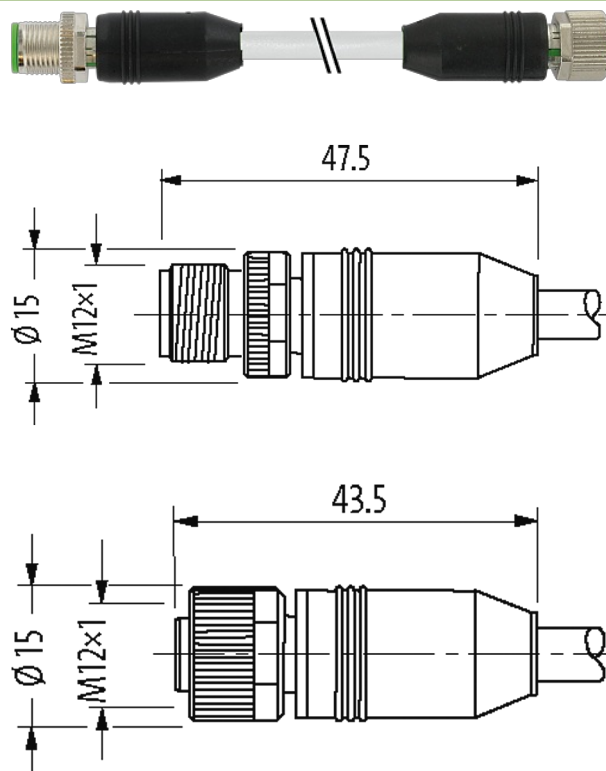Illustration

Product may differ from Image


Sketch

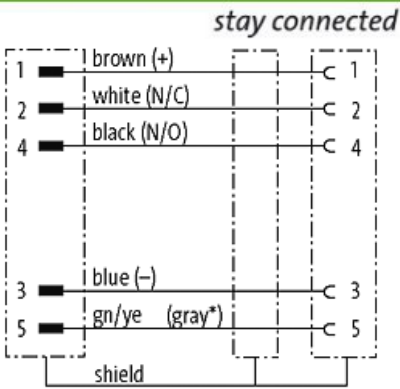

(* for cable type 203, 603, 243, 643)

Male

Female

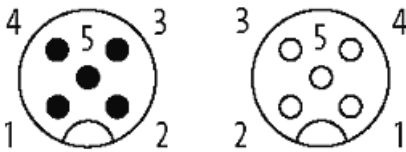

Product may differ from Image