

M12 male 90° / M8 female 90°

PVC 3x0.25 ye UL/CSA 0,3m



Male 90° – female 90°

M12 – M8, 3-pole

Plastic housings with good resistance against chemicals and oils.



The resistance to aggressive media should be individually tested for your application. Further details on request.

Further cable lengths on request.

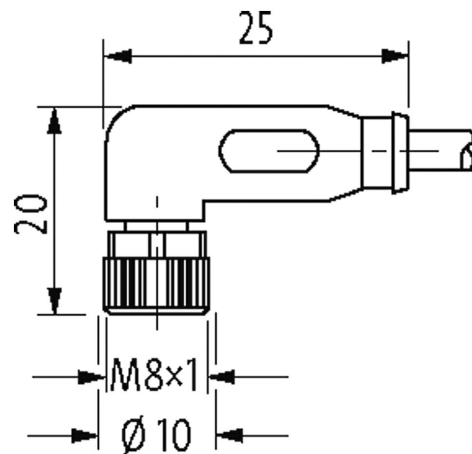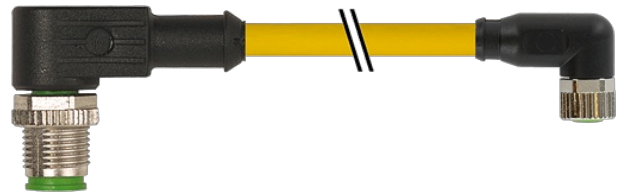[Link to Product](#)**Illustration**


Product may differ from Image

Sketch

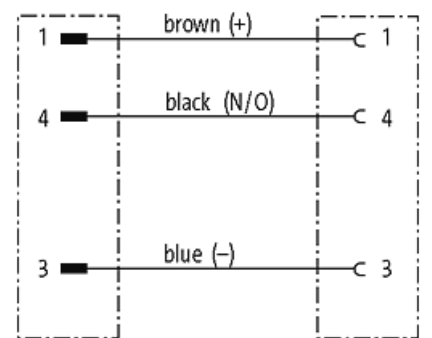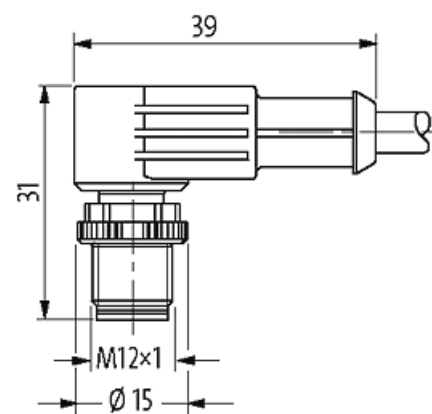

Male

Female

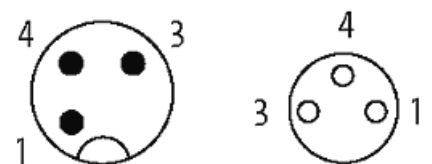

Product may differ from Image