

M12 MALE 90° / MSUD VALVE PLUG FORM B 10 MM

PUR 3X0.75 YELLOW, UL/CSA, drag ch 1.5m

Form B (10 mm) – M12, male 90°

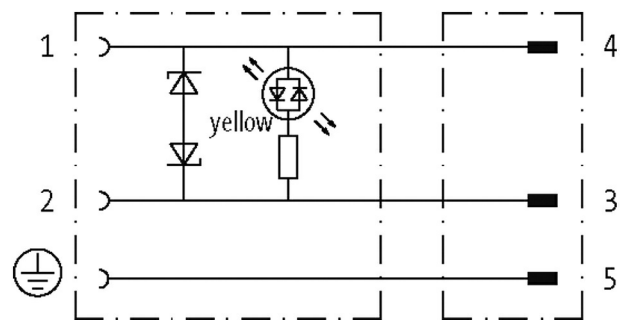
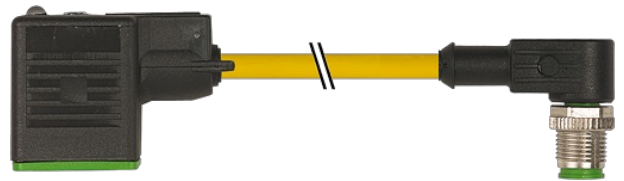
24 V AC $\pm 20\%$ / DC $\pm 25\%$

LED and suppression

Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

Product may differ from Image