

T-COUPLER SLIMLINE(LED)M12-MALE 5P/2XM12-FEMALE 4P

T-coupler (Slim Line)

Male straight – females straight

M12 – M12


5-pole

3× LED (PNP)

Distribution function (NO)

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

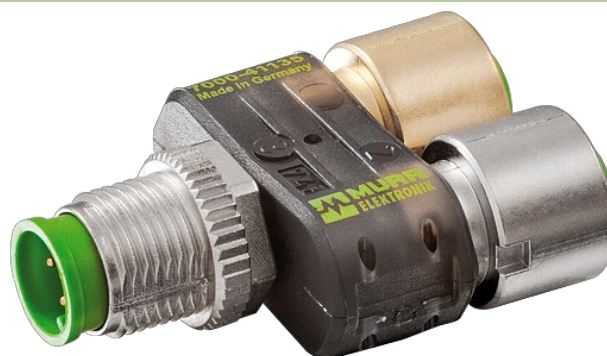Illustration

Product may differ from Image

Approvals**Form**

Form 41135

Technical Data

Operating voltage	24 V DC $\pm 25\%$
Operating voltage (only UL listed)	30 V DC
Rated surge voltage	0.8 kV
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)

General data




Temperature range -25...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879144858
eClass	27143423
Packaging unit	1

Sketch

stay connected

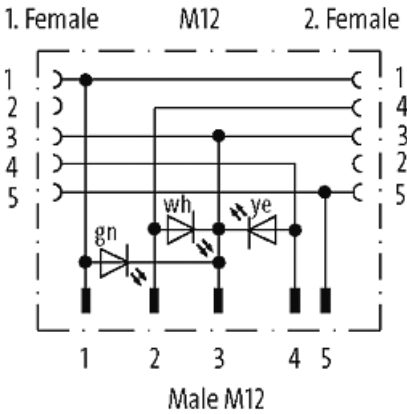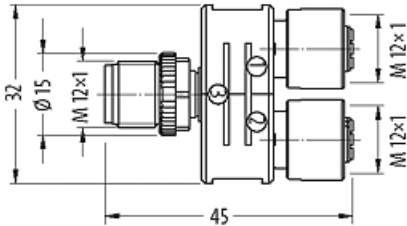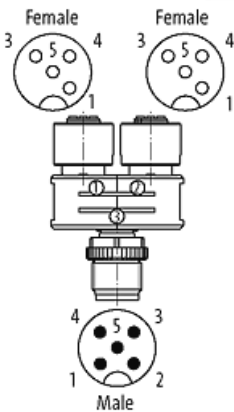

Product may differ from Image