

T COUPLER SLIMLINE M12 MALE / M12 FEMALE 0°

T-coupler (Slim Line)
 Male straight – females straight
 M12 – M12, 4-pole
 Series connection

Illustration

Product may differ from Image

Approvals**Form**

Form 41165

Technical Data

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Rated surge voltage	1.5 kV

General data



Temperature range -25...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879144810
eClass	27143423
Packaging unit	1

Sketch

stay connected

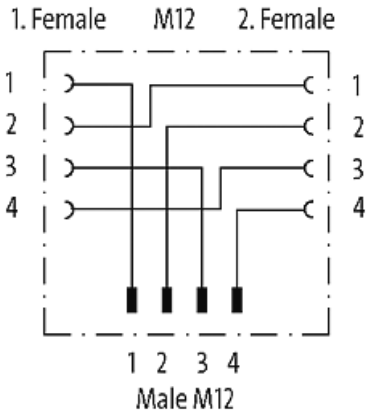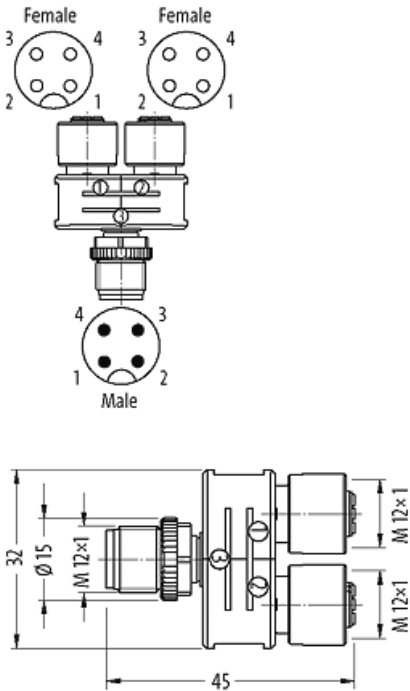

Product may differ from Image