

T-COUPLER SLIMLINE M12 MALE / 2X M8 FEMALE

T-coupler (Slim Line)


Male straight – females straight

M12 – M8, 3-pole

Parallel circuit

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

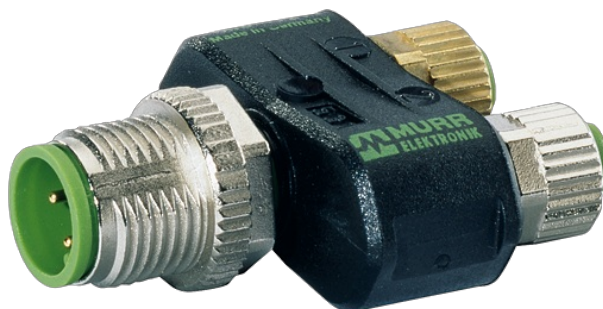Illustration

Product may differ from Image

Approvals**Form**

Form 41231

Technical Data

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M8/M12×1 mm) recommended torque 0.4/0.6 Nm, self-securing
Protection	IP65 and IP67 when plugged and screwed down (EN 60529)
Rated surge voltage	1.5 kV

General data




Temperature range -25...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879144759
eClass	27143423
Packaging unit	1

Sketch

stay connected

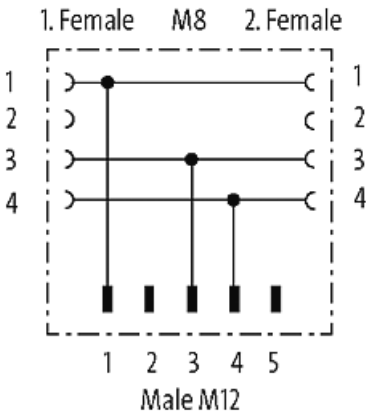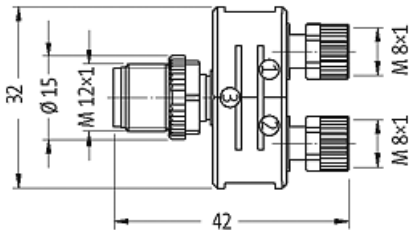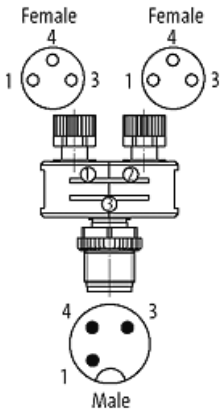

Product may differ from Image