

M12 ADAPTOR ON TOP OF MSUD VALVE PLUG FORM A 18MM

Form A (18 mm) – M12, connector top entry

110 V AC/DC $\pm 10\%$

without components

3-pole

Plastic housings with good resistance against chemicals and oils.




The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration




Female

Male

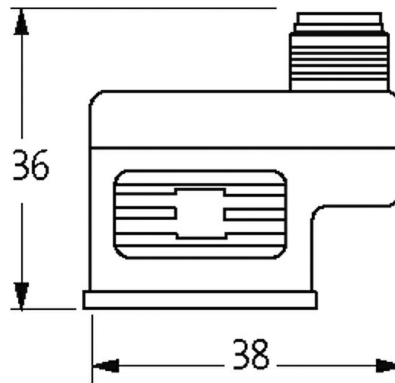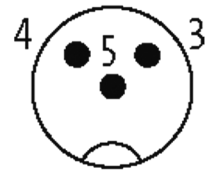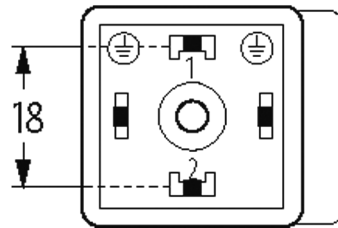

Depth: 27 mm

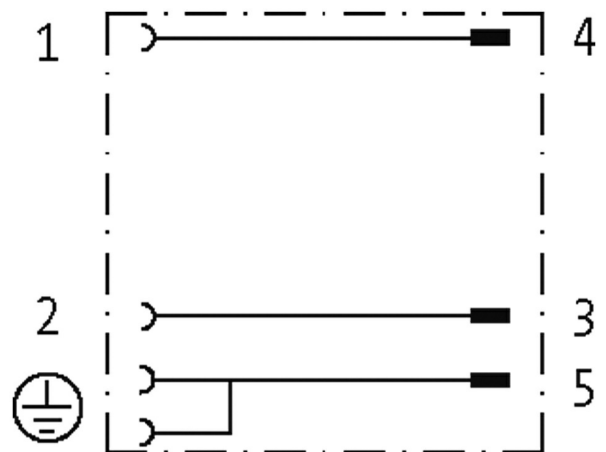

Product may differ from Image

Approvals**Form**

Form 41261

Technical Data

Operating voltage	110 V AC/DC
Rated surge voltage	1.5 kV
Operating current per contact	max. 4 A
Material group	IEC 60664-1, category I
Configuration	2 contacts + bridged PE
Coding	M12, A-coded
Locking of ports	M3/M12×1 mm (recommended torque 0.4/0.6 Nm)
Protection	IP67 inserted and tightened (EN 60529)

General data

Pollution Degree	3
Temperature range	-25...+85 °C

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879144728
eClass	27143423
Packaging unit	1