

M12 ADAPTOR ON TOP OF MSUD VALVE PLUG FORM A 18MM

Form A (18 mm) – M12, connector top entry

24 V DC $\pm 25\%$


for pressure switches

LED (yellow/green)


5-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

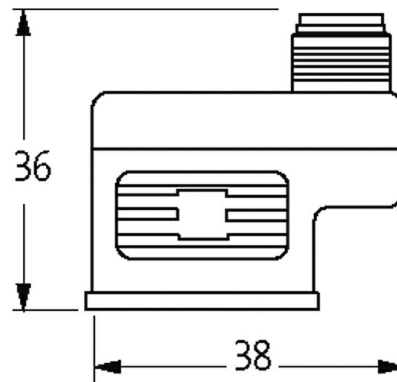Illustration

Depth: 27 mm

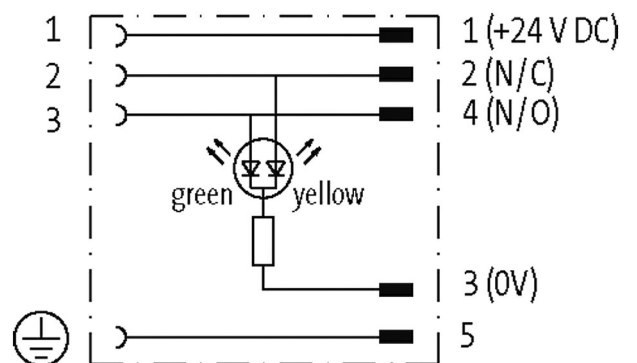

Product may differ from Image

Approvals**Form**

Form 41321

Technical Data

Operating voltage	24 V DC \pm 25%
Rated surge voltage	0.8 kV
Operating current per contact	max. 4 A
Configuration	3 contacts + PE
Locking of ports	M3/M12 \times 1 mm (recommended torque 0.4/0.6 Nm)
Protection	IP67 inserted and tightened (EN 60529)

General data

Temperature range -25...+85 °C

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879144681
eClass	27143423
Packaging unit	1