

**M12 ADAPTOR ON REAR OF MSUD VALVE PLUG FORM A 18MM**

Form A (18 mm) – M12, connector at the rear

110 V AC/DC  $\pm 10\%$

without components

3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.



**Illustration**

*stay connected*




Female

Male

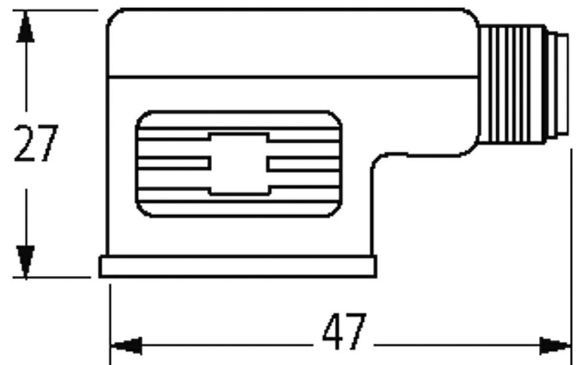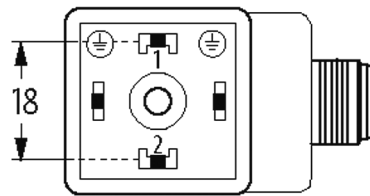

Depth: 27 mm

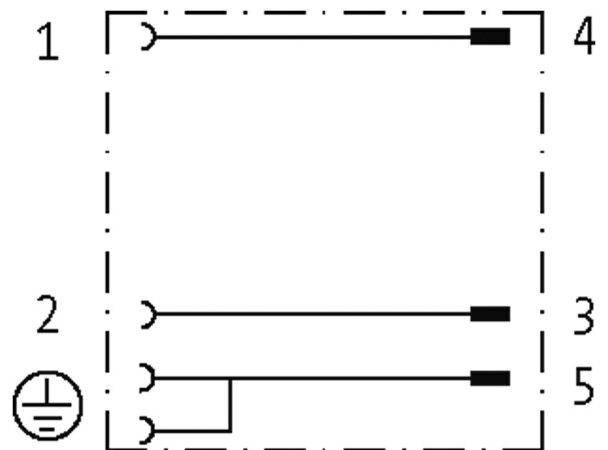

Product may differ from Image

**Approvals**

**Form**

Form	41381
------	-------

**Technical Data**

Operating voltage	110 V AC/DC $\pm 10\%$
Operating current per contact	max. 4 A
Configuration	2 contacts + bridged PE
Protection	IP67 inserted and tightened (EN 60529)
Locking of ports	M3/M12 $\times$ 1 mm (recommended torque 0.4/0.6 Nm)
Rated surge voltage	1.5 kV

**General data**

Temperature range	-25...+85 °C
-------------------	--------------

**Commercial data**

country of origin	CZ
customs tariff number	85366990
EAN	4048879144643
eClass	27143423
Packaging unit	1