

M12 adaptor on back/MSUD v plug form A 18mm 180°

Form A (18 mm) – M12, connector at the rear
for pressure switches


24 V DC $\pm 25\%$

LED (yellow/green)


5-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

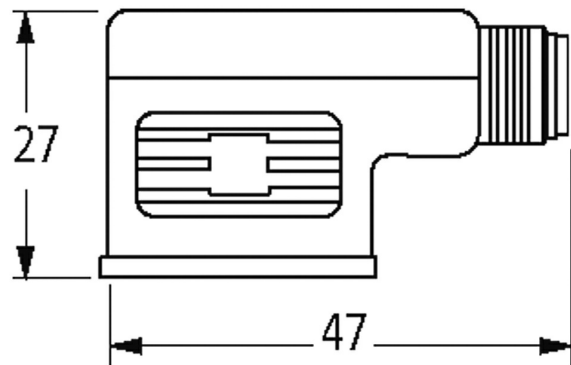Illustration

Depth: 27 mm

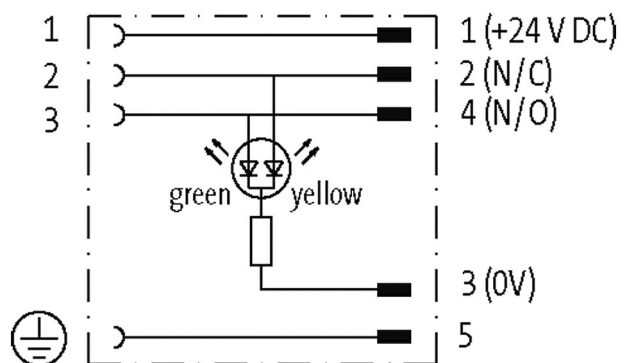

Product may differ from Image

Approvals**Form**

Form 41445

Technical Data

Operating voltage	24 V DC \pm 25%
Operating current per contact	max. 4 A
Locking of ports	M3 (recommended torque 0.4 Nm)
Protection	IP67 inserted and tightened (EN 60529)

General data

Temperature range -25...+90 °C

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879596145
eClass	27279218
Packaging unit	1