

**M12 MALE ON TOP OF MSUD VALVE PLUG FORM B 10 MM**

Form B (10 mm) – M12, connector top entry

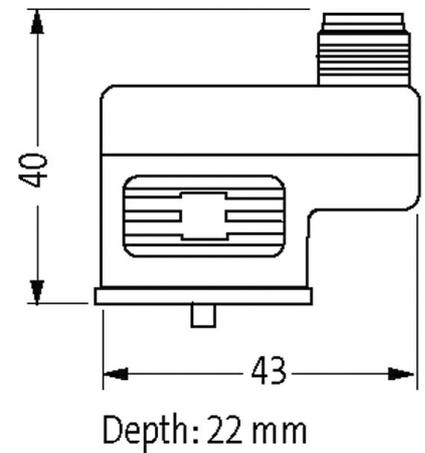
max. 125 V AC/DC

without components

3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

**Illustration**

Product may differ from Image

**Approvals****Form**

Form 41861

**Technical Data**

Operating voltage max. 125 V AC/DC

Operating current per contact max. 4 A

Configuration 2 contacts + PE

Protection	IP67 inserted and tightened (EN 60529)
Locking of ports	M3/M12×1 mm (recommended torque 0.4/0.6 Nm)

**General data**

Temperature range	-25...+85 °C
-------------------	--------------

**Commercial data**

country of origin	CZ
customs tariff number	85366990
EAN	4048879143493
eClass	27143423
Packaging unit	1