

M12 MALE ON REAR OF MSUD VALVE PLUG FORM B 10 MM

Form B (10 mm) – M12, connector at the rear

24 V AC/DC $\pm 25\%$

LED (yellow)

3-pole

Plastic housings with good resistance against chemicals and oils.



The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration




Female

Male

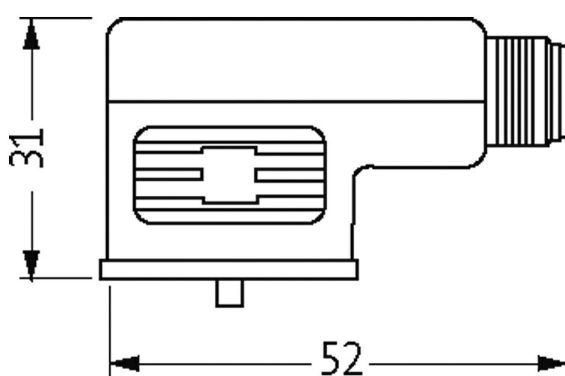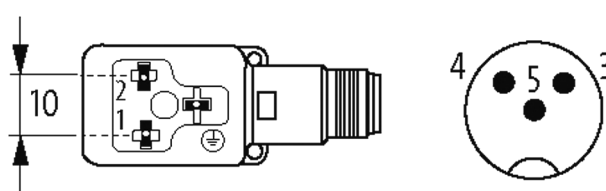

Depth: 22 mm

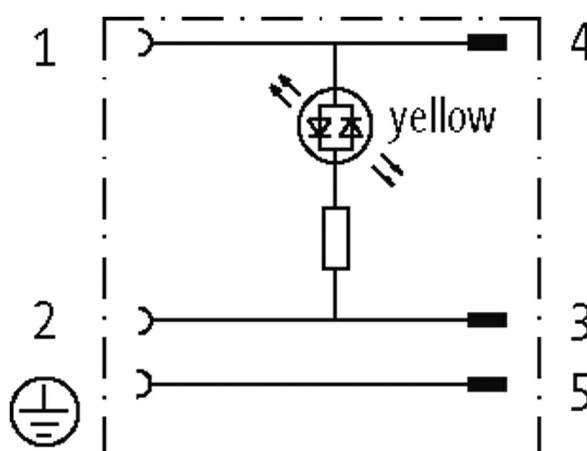

Product may differ from Image

Approvals

**Form**

Form	41941
------	-------

Technical Data

Operating voltage	24 V AC/DC $\pm 25\%$
Operating current per contact	max. 4 A
Configuration	2 contacts + PE
Protection	IP67 inserted and tightened (EN 60529)
Locking of ports	M3/M12 $\times$ 1 mm (recommended torque 0.4/0.6 Nm)

General data

Temperature range	-25...+85 °C
-------------------	--------------

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879143363
eClass	27143423
Packaging unit	1