

T-COUPLER 5 POLEMALE./4 POLEFEMALE M12 SHIELDED

T-coupler

Male straight – females straight

M12 – M12

5-pole

shielded


Distribution function (NO)

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

Product may differ from Image

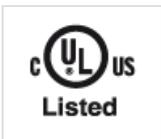Approvals**Form**

Form 42121

Technical Data

Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

General data

Temperature range -25...+85 °C

Commercial data

country of origin DE

customs tariff number 85366990



EAN 4048879143226

eClass 27143423


Packaging unit 1

Sketch

stay connected

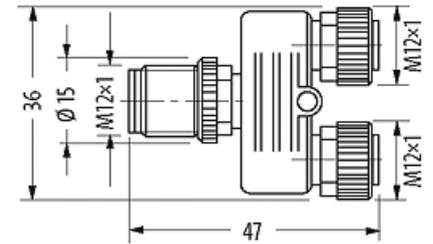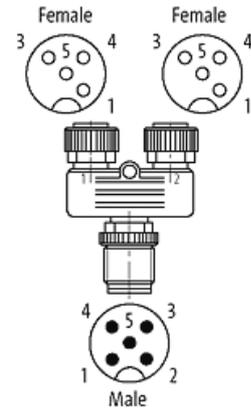

1. Female M12 2. Female

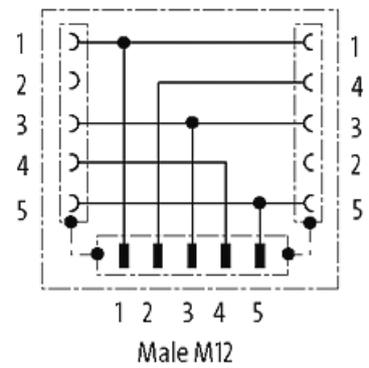

Product may differ from Image