

M12 ADAPTOR ON TOP / MSUD VALVE PLUG FORM CI 9.4 MM

Form CI (9.4 mm) – M12, connector top entry

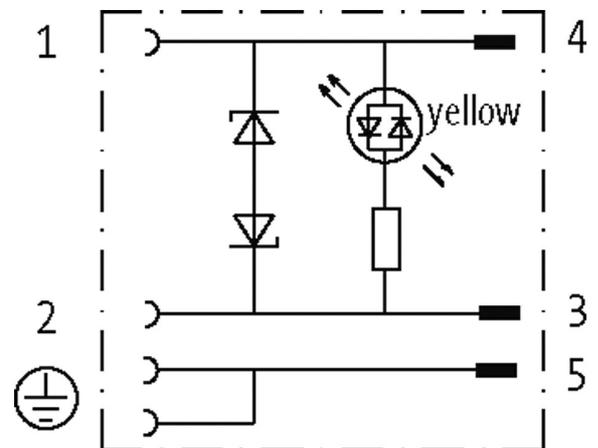
24 V AC $\pm 20\%$ / DC $\pm 25\%$

LED and suppression

3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

Product may differ from Image

Approvals**Form**

Form 42851

Technical Data

Operating voltage 24 V AC $\pm 20\%$ / DC $\pm 25\%$

Operating current per contact max. 4 A

Current consumption max. 15 mA

Configuration	2 contacts + bridged PE
Switch off peak	max. 55 V
Locking of ports	M3/M12×1 mm (recommended torque 0.4/0.6 Nm)
Protection	IP67 inserted and tightened (EN 60529)

General data

Temperature range	-25...+85 °C
-------------------	--------------

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879348720
eClass	27143423
Packaging unit	1