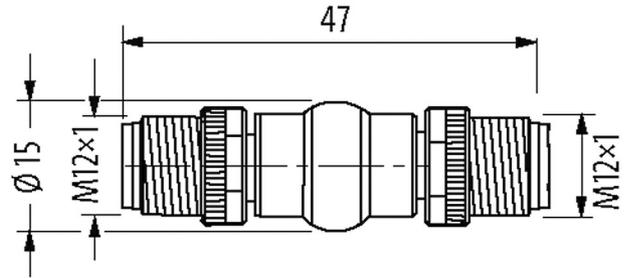


**M12 ADAPTOR MALE B-CODED / M12 MALE B-CODED**

Adapter  
 Male - male  
 M12 – M12, 2-pole  
 B-coded  
 shielded

**Illustration**

Product may differ from Image

**Form**

Form 44201

**Technical Data**

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M12x1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated
Material	PUR
Rated surge voltage	1.5 kV

**General data**

Temperature range	-25...+85 °C
Test isolation voltage	0.8 kV eff/rms

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879317481
eClass	27143423
Packaging unit	1