

M12 bulkhead receptacle Y-cod.

Ethernet CAT5
 Control cabinet entry system
 Male - female
 M12, 8-pole
 Y-coded
 shielded

[Link to Product](#)**Illustration**

Product may differ from Image

More Info


EtherNet/IP

Form

Form 47281

General data

Pollution Degree	3
Mounting set	M16×1.5 mm
Temperature range	-25...+85 °C


Technical Data

Operating voltage	max. 30 V DC
Rated surge voltage	0.8 kV
Operating current per contact	max. 6 A
Operating current per contact (Signal)	max. 0.5 A
Material group	IEC 60664-1, category I
Transfer parameters	CAT5, Class D (ISO/IEC 11801:2002), (EN 50173-1)
Transfer rate	up to 100 Mbit/s full duplex
Coding	Y-coded
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Compression gland	M16 (SW19)
Protection	IP65 and IP67 when plugged and screwed down (EN 60529)
Material	Brass, nickel plated

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879600385
eClass	27143423
Packaging unit	1

Sketch

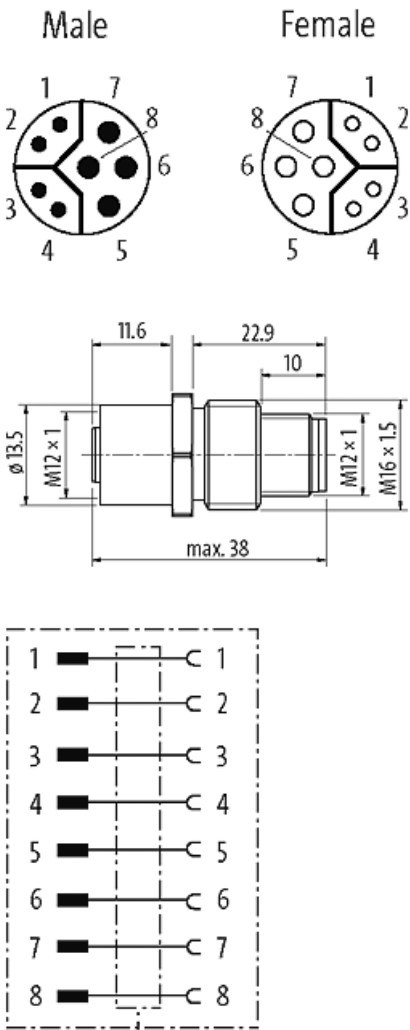

Product may differ from Image