

**T-coupler M12 male / M12 female 8p.**

T-coupler


Male straight – females straight

M12 – M12, 8-pole

Parallel circuit

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

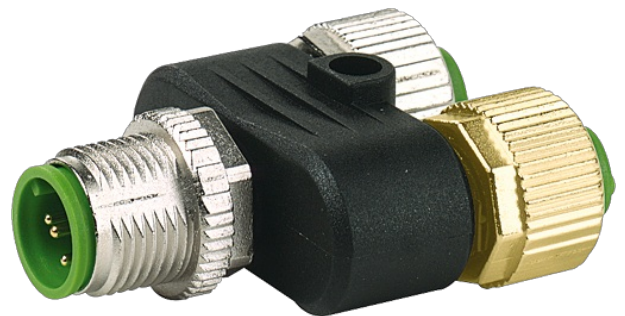**[Link to Product](#)****Illustration**

Product may differ from Image

**Approvals**

\* only for products with UL/CSA approved cable

**Form**

Form 48151

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage max. 30 V AC/DC

Operating voltage (only UL listed) max. 30 V AC/DC

Rated surge voltage 0.8 kV

Operating current per contact max. 2 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

**Commercial data**

country of origin DE




customs tariff number 85366990

EAN 4048879470155

eClass 27143423

Packaging unit 1

**Sketch**

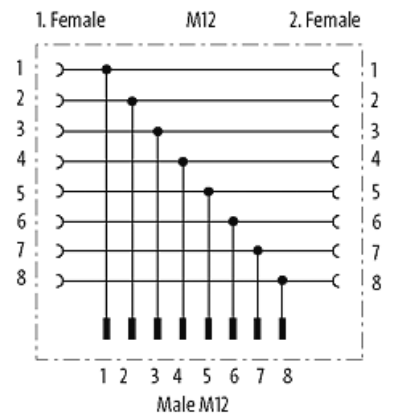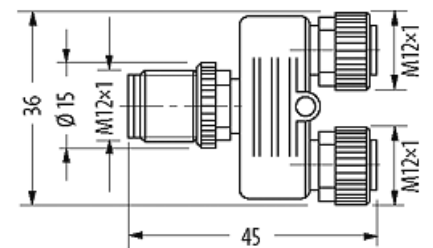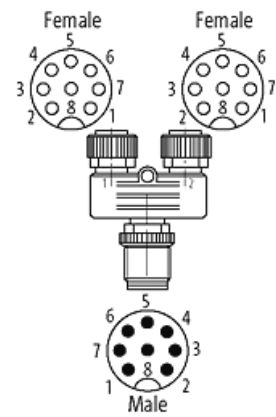

Product may differ from Image