

T coupler 7/8" male / 2x 7/8" female 3p

T-coupler

Female straight – female/male straight

7/8" – 7/8", 3-pole

Parallel circuit

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form 50071

General data

Pollution Degree 3

Temperature range -30...+90 °C

Technical Data

Operating voltage max. 250 V AC/DC

Rated surge voltage 4.0 kV

Operating current per contact max. 10 A

Material group IEC 60664-1, category II

Locking of ports Screw thread 7/8" (recommended torque 1.5 Nm) self-securing

Compression gland 7/8" (SW24)

Protection IP67 inserted and tightened (EN 60529)

Locking material Zinc die casting, matte nickel plated

Material PA

suitable for corrugated tube (internal Ø) without

Housing PA

Commercial data

country of origin DE


customs tariff number 85366990

EAN 4048879631426

eClass 27143423

Packaging unit 1

Sketch

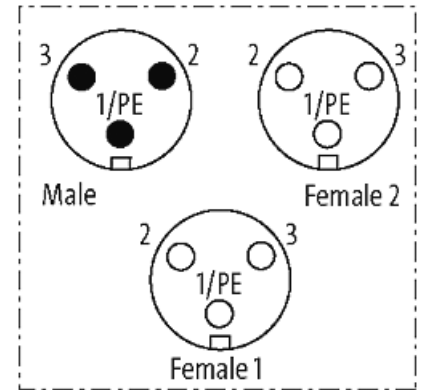

Product may differ from Image