

**adaptor M12 female x-cod. / RJ45 male 0° Gigabit**

Adapter  
M12 – RJ45  
Female straight – female straight  
8-pole  
X-coded  
Gigabit  
Ethernet CAT6A  
shielded  
Cap nut



**[Link to Product](#)**

**Illustration**





Female

Female

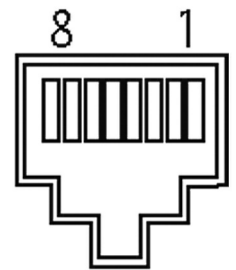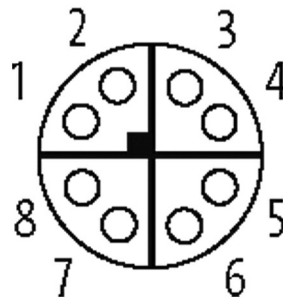

panel cut out

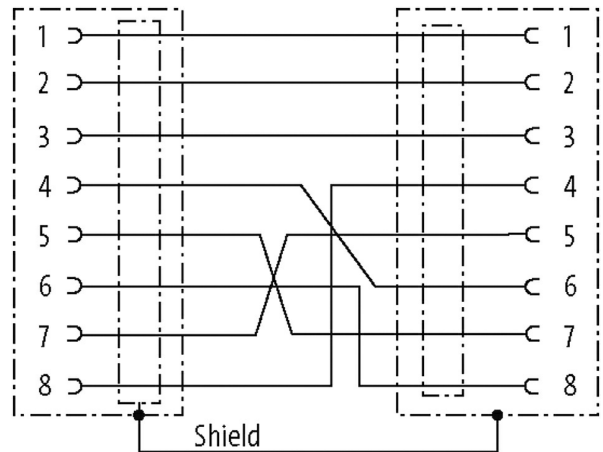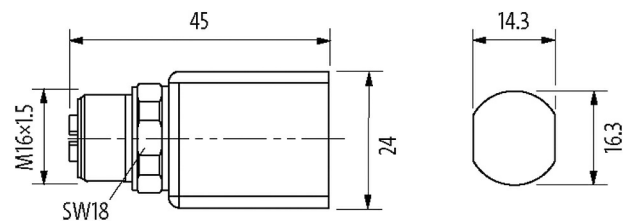

Product may differ from Image

**Form**

Form 51531

**General data**

Mounting plate thickness 2.1...4.5 mm

**Technical Data**

Operating current max. 1.75 A

Transfer parameters Ethernet CAT6A

Coding X-coded

Compression gland M12 (SW18)

**Commercial data**

country of origin RO

customs tariff number 85366990

EAN 4048879699402

eClass 27143423

Packaging unit 1