

**adaptor M12 female x-cod. / RJ45 male 90° Gigabit**

Adapter  
M12 – RJ45, top connection  
Female straight – female 90°  
8-pole  
X-coded  
Gigabit  
Ethernet CAT6A  
shielded  
Cap nut




[Link to Product](#)

Illustration



Female

Female

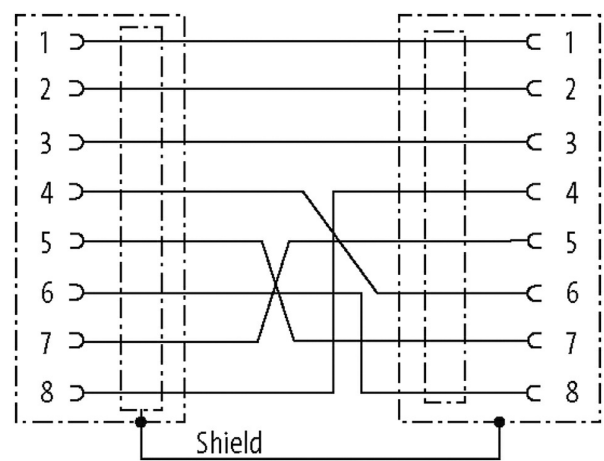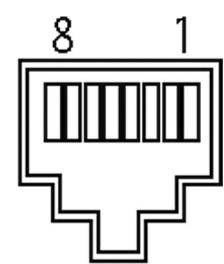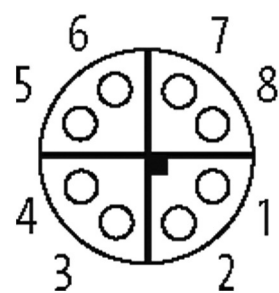

Product may differ from Image

| Form                     |                |
|--------------------------|----------------|
| Form                     | 51541          |
| General data             |                |
| Mounting plate thickness | 2.1...4.5 mm   |
| Technical Data           |                |
| Operating current        | max. 1.75 A    |
| Transfer parameters      | Ethernet CAT6A |
| Coding                   | X-coded        |

Compression gland M12 (SW18)

**Commercial data**

country of origin DE

customs tariff number 85366990

EAN 4048879699419

eClass 27143423

Packaging unit 1