


RJ45 St. 0jÆ / RJ45 St. 0jÆ, Gigabit

FRNC/LS0H 4x2xAWG26 shielded gn UL 5m

Ethernet CAT6A
Male straight – male straight
RJ45 – RJ45, 8-pole
shielded
with cable sleeves
Further cable lengths on request.
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.



[Link to Product](#)

Illustration

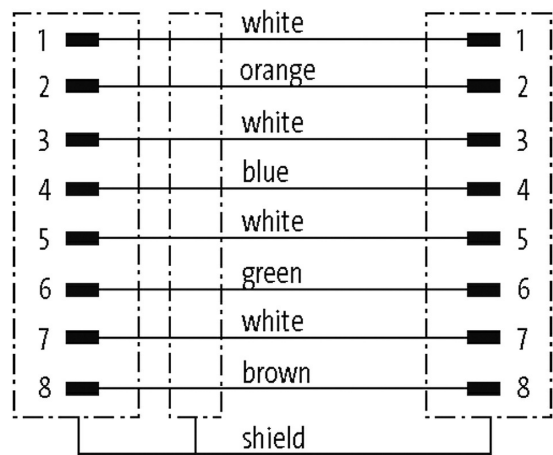

Product may differ from Image

Sketch

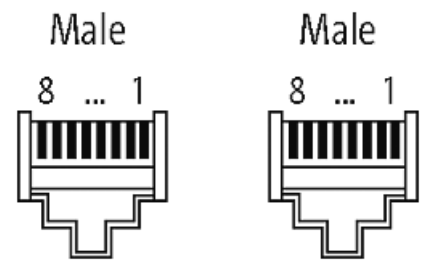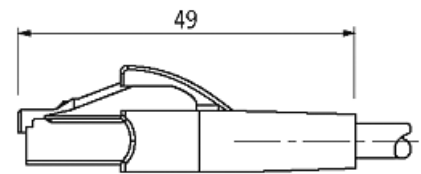

Product may differ from Image