


M8 panel feed through 3p shielded

Control cabinet entry system
Male - female
M8, 3-pole
Rear mounting
shielded

[Link to Product](#)

Illustration

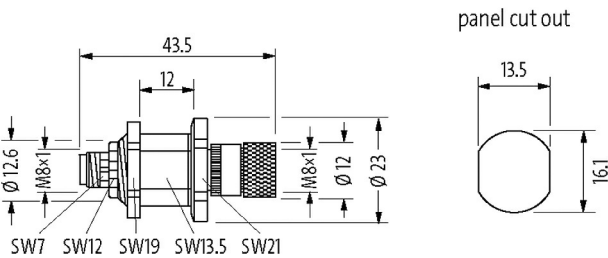

Product may differ from Image


Form	
Form	88111
General data	
Mounting plate thickness	1...12 mm
Mounting method	inserted, tightened
Material (contact carrier)	PA
Material (contact)	Copper alloy
Material (contact surface)	Au
Pollution Degree	3
Temperature range	-25...+85 °C
Technical Data	
Operating voltage	250 V
Rated surge voltage	2.5 kV
Operating current per contact	max. 4 A
No. of poles	3
Material group	3
LED display	no
Compression gland	M8
Protection	IP67 inserted and tightened (EN 60529)

Housing	Metal
suitable for corrugated tube (internal Ø)	without
Over voltage category	2
Mating cycles	≥ 100

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879689298
eClass	27143423
Packaging unit	1

Sketch

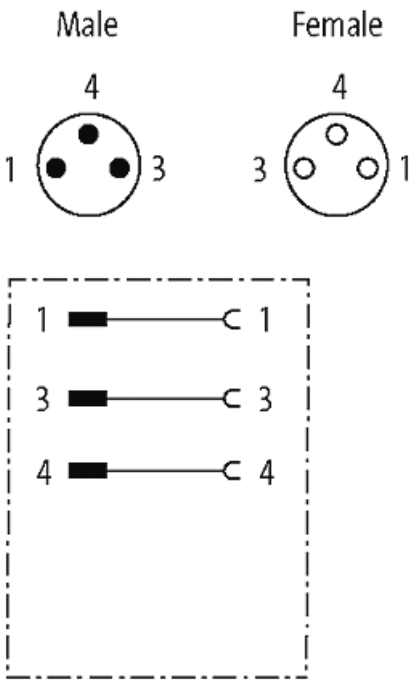

Product may differ from Image