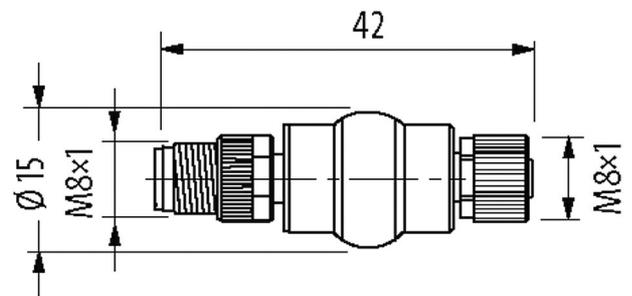


ADAPTOR M8 MALE / M8 FEMALE CONF. 1,3,4

Adapter

Male - female

M8 – M8, 4/3-pole

Illustration

Product may differ from Image

Approvals**Form**

Form 88501

General data

Temperature range -25...+85 °C
 Test isolation voltage 0.8 kV eff/rms


Technical Data

Operating voltage	max. 50 V AC/DC
Operating voltage (only UL listed)	max. 30 V AC/DC
Rated surge voltage	1.5 kV
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated
Material	PUR

Commercial data

country of origin DE

customs tariff number	85366990
EAN	4048879118545
eClass	27143423
Packaging unit	1

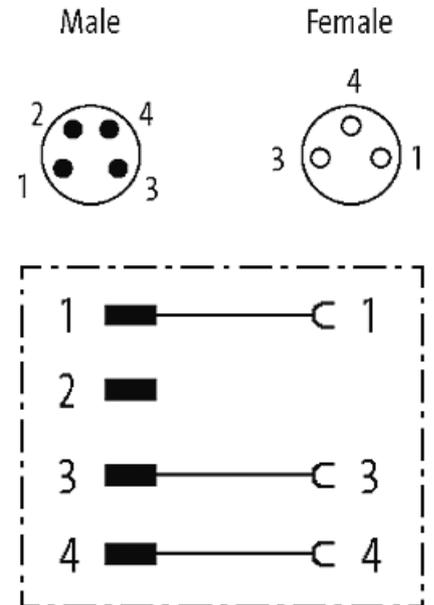Sketch

Product may differ from Image