


ADAPTOR M8 MALE / M8 FEMALE CONF. 1,3,4


Adapter
Male - female
M8 – M8, 3/4-pole

Illustration

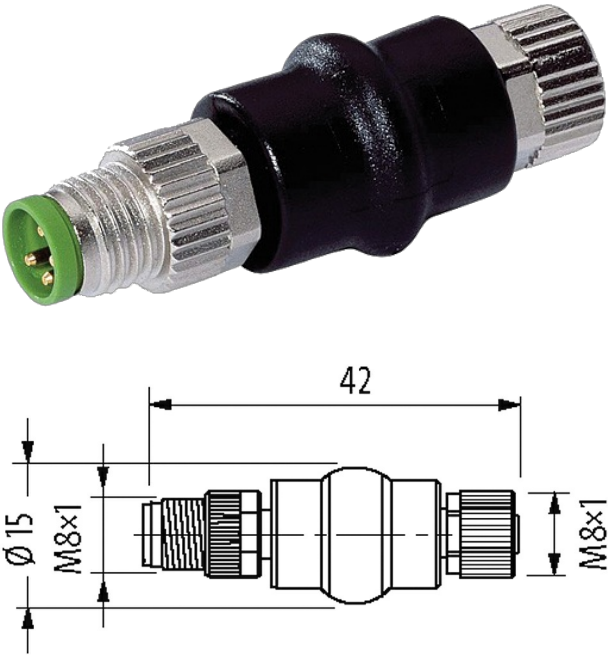

Product may differ from Image

Approvals

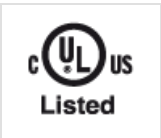

Form

Form 88511

General data


Test isolation voltage	0.8 kV eff/rms
Pollution Degree	3
Temperature range	-25...+85 °C

Technical Data

Operating voltage	max. 50 V AC/60 V DC
Operating voltage (only UL listed)	max. 30 V AC/DC
Rated surge voltage	1.5 kV
Operating current per contact	max. 4 A
Material group	IEC 60664-1, category I
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Compression gland	M8 (SW9)
Protection	IP67 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated

Material PUR

Commercial data	
country of origin	DE
customs tariff number	85366990
EAN	4048879118538
eClass	27143423
Packaging unit	1
Sketch	

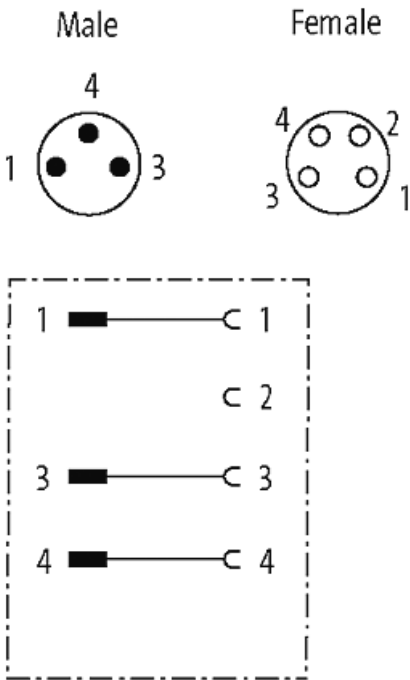

Product may differ from Image