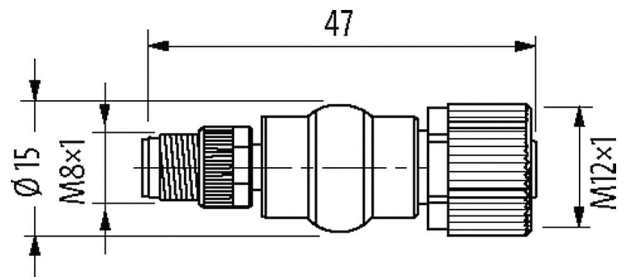
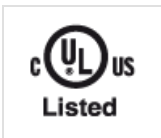


ADAPTOR M8 MALE 3 POLE/ M12 FEMALE CONF. 1,3,4

Adapter
 Male - female
 M8 – M12, 3-pole
 for M8 distribution box 3-pole

Illustration

Product may differ from Image

Approvals**Form**

Form 88521

Technical Data


Operating voltage	max. 50 V AC/60 V DC
Operating voltage (only UL listed)	max. 30 V AC/DC
Rated surge voltage	0.8 kV
Operating current per contact	max. 4 A
Material group	IEC 60664-1, category I
Coding	A-coded
Locking of ports	Screw thread (M8/M12×1 mm) recommended torque 0.4/0.6 Nm, self-securing
Compression gland	M8 (SW9), M12 (SW13)
Protection	IP67 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated
Material	PUR

General data

Test isolation voltage	0.8 kV eff/rms
Pollution Degree	3
Temperature range	-25...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879118521
eClass	27143423
Packaging unit	1

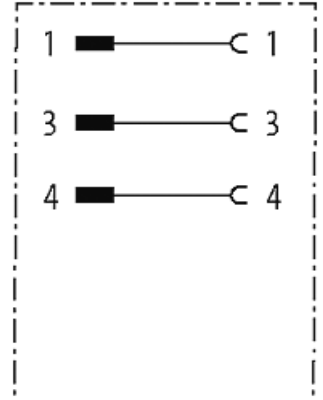Sketch

Product may differ from Image