

T-COUPLER SLIMLINE M8-MALE 4 POLE/ 2X M8-FEMALE 3P

T-coupler (Slim Line)

Male straight – females straight

M8 – M8, 4-pole


Distribution function (NO)

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

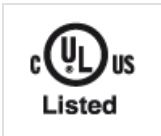Approvals**Form**

Form 88601

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage max. 30 V AC/DC

Operating current per contact max. 4 A

Locking of ports Screw thread (M8x1 mm) recommended torque 0.4 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Rated surge voltage 0.8 kV

Commercial data

country of origin DE




customs tariff number 85366990

EAN 4048879118507

eClass 27143423

Packaging unit 1

Sketch

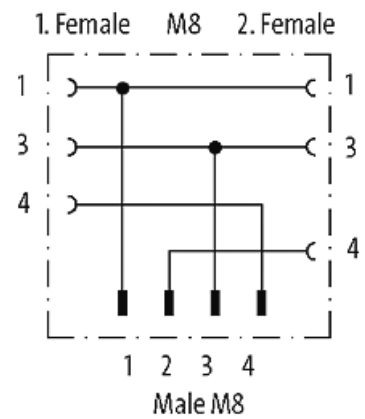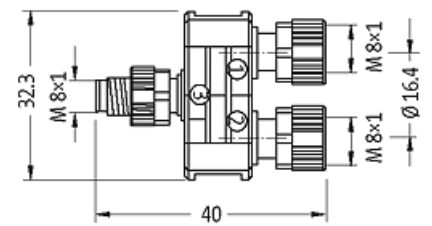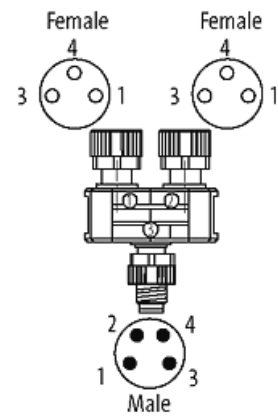

Product may differ from Image