

M8 ADAPTOR ON REAR OF MSUD VALVE PLUG FORM B 10 MM

LED+Suppression 24 V AC/DC

Form B (10 mm) – M8, connector at the rear

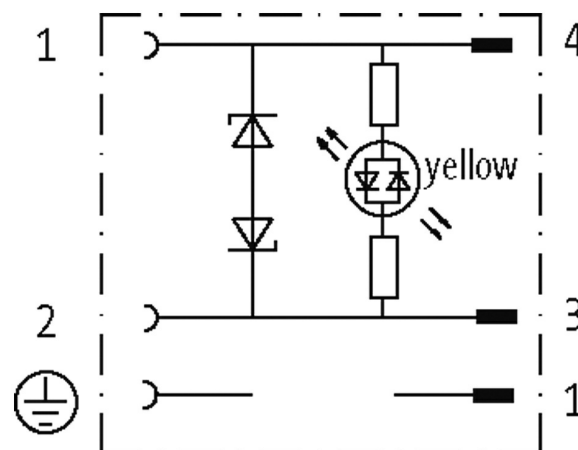
24 V AC $\pm 20\%$ / DC $\pm 25\%$

LED and suppression

3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Form**

Form 88935

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage 24 V AC $\pm 20\%$ / DC $\pm 25\%$

Operating current per contact max. 4 A

Current consumption max. 15 mA

Configuration 2 contacts + PE

Switch off peak max. 55 V

Locking of ports M3/M8 (recommended torque 0.4 Nm)

Protection IP67 inserted and tightened (EN 60529)

Rated surge voltage 0.8 kV

Commercial data

country of origin CZ

customs tariff number 85366990

EAN 4048879115919

eClass 27143423

Packaging unit 1