

## **M8 ADAPTOR ON TOP OF MSUD VALVE PLUG FORM BI 11MM**

LED+Suppression 24 V AC/DC

Form BI (11 mm) – M8, connector top entry

24 V AC  $\pm 20\%$  / DC  $\pm 25\%$

LED and suppression



3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

### **[Link to Product](#)**

#### **Illustration**

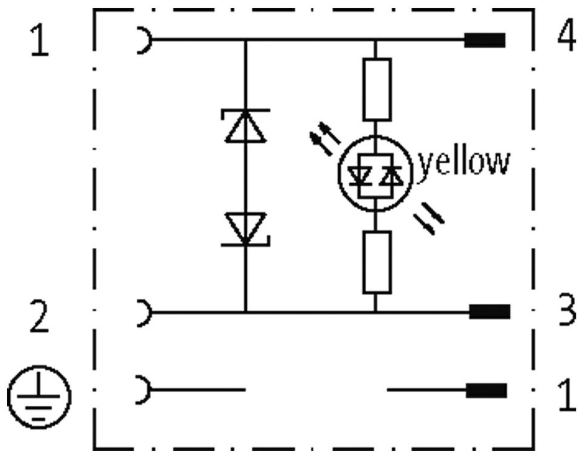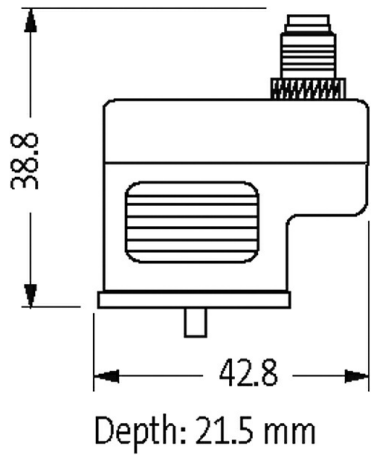

Product may differ from Image

**Approvals**



**Form**

Form 88945

**General data**

|                   |              |
|-------------------|--------------|
| Temperature range | -25...+85 °C |
|-------------------|--------------|

**Technical Data**

|                   |                                    |
|-------------------|------------------------------------|
| Operating voltage | 24 V AC $\pm 20\%$ / DC $\pm 25\%$ |
|-------------------|------------------------------------|

|                               |          |
|-------------------------------|----------|
| Operating current per contact | max. 4 A |
|-------------------------------|----------|

|                 |           |
|-----------------|-----------|
| Switch off peak | max. 55 V |
|-----------------|-----------|

|               |                 |
|---------------|-----------------|
| Configuration | 2 contacts + PE |
|---------------|-----------------|

|                     |            |
|---------------------|------------|
| Current consumption | max. 15 mA |
|---------------------|------------|

|            |                                        |
|------------|----------------------------------------|
| Protection | IP67 inserted and tightened (EN 60529) |
|------------|----------------------------------------|

|                  |                                   |
|------------------|-----------------------------------|
| Locking of ports | M3/M8 (recommended torque 0.4 Nm) |
|------------------|-----------------------------------|

|                     |        |
|---------------------|--------|
| Rated surge voltage | 0.8 kV |
|---------------------|--------|

**Commercial data**

|                   |    |
|-------------------|----|
| country of origin | CZ |
|-------------------|----|

|                       |          |
|-----------------------|----------|
| customs tariff number | 85366990 |
|-----------------------|----------|

|     |               |
|-----|---------------|
| EAN | 4048879115889 |
|-----|---------------|

|        |          |
|--------|----------|
| eClass | 27143423 |
|--------|----------|

|                |   |
|----------------|---|
| Packaging unit | 1 |
|----------------|---|