

**M8 ADAPTOR ON REAR OF MSUD VALVE PLUG FORM BI 11MM**

LED+Suppression 24 V AC/DC

Form BI (11 mm) – M8, connector at the rear

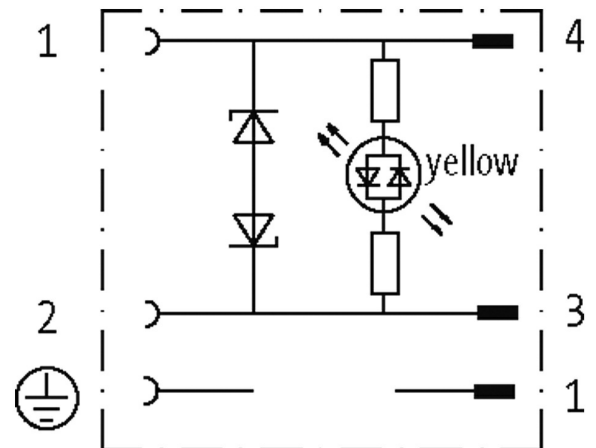
24 V AC  $\pm 20\%$  / DC  $\pm 25\%$ 

LED and suppression

3-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals****Form**

Form

88955

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage 24 V AC  $\pm 20\%$  / DC  $\pm 25\%$

Operating current per contact max. 4 A

Current consumption max. 15 mA

Configuration 2 contacts + PE

Switch off peak max. 55 V

Locking of ports M3/M12 $\times$ 1 mm (recommended torque 0.4/0.6 Nm)

Protection IP67 inserted and tightened (EN 60529)

Rated surge voltage 0.8 kV

**Commercial data**

country of origin CZ

customs tariff number 85366990

EAN 4048879115858

eClass 27143423

Packaging unit 1