

CABLE GLAND PA M12X 1.5

Cable compression gland
 metric
 M12×1.5 mm
 (gray)
 (conduit on request)
 Quantity: 100 pcs.

[Link to Product](#)**Illustration**

Product may differ from Image

Form

Form	91001
------	-------

General data

Gasket	NBR
Temperature range	-20...+100 °C
Mounting set	M12×1.5 mm
Dimensions H×W×D	31×15×15 mm
Thread length	8 mm


Technical Data

Protection	IP68
Material	PA
Sealing range (cable Ø)	3...6 mm
Compression gland	M12 (SW15)

Commercial data

country of origin	DE
customs tariff number	39174000
EAN	4048879468237
eClass	27279221
Packaging unit	100

Sketch

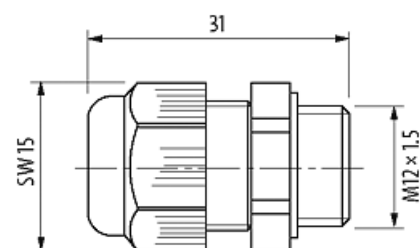

Product may differ from Image