

**M12/D-SUB PROFIBUS ADAPTER 90°**


M12 male B-cod./M12 female B-cod.

**PROFIBUS**

Bus connection plug 90°

SUB-D9 (male); M12× 1 mm, B-coded

Programming device

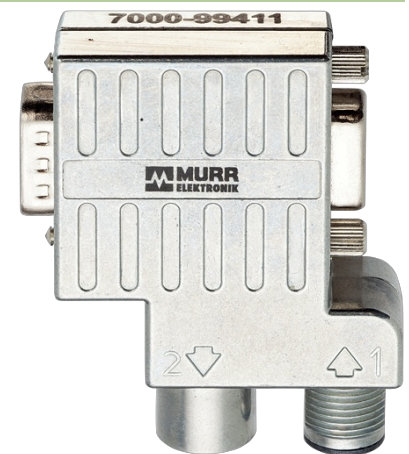[Link to Product](#)**Illustration**

Product may differ from Image

**Form**

Form 99411

**General data**

Dimensions H×W×D 59×45×17 mm

Temperature range -20...+70 °C

**Technical Data**

Operating voltage 4.75...5.25 V DC (via the fieldbus device)

Current consumption max. 12.5 mA

Transfer rate max. 12 Mbit/s

Connection M12×1 mm

Terminating resistor integrated, switchable

Protection IP30

**Commercial data**

country of origin HU


customs tariff number 85366990

EAN 4048879303637

eClass 27061801

Packaging unit 1

**Sketch**

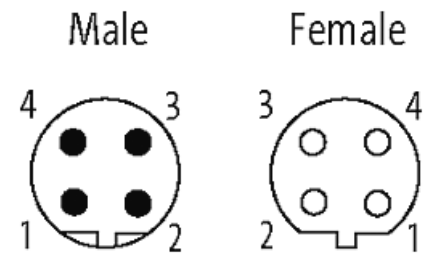

Product may differ from Image