

**M12/D-SUB PROFIBUS ADAPTER MINI 90°**

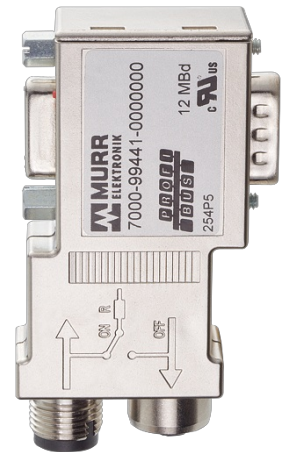
M12 male B-cod./M12 female B-cod.

**PROFIBUS**

Bus connection plug 90°

SUB-D9 (male); M12× 1 mm, B-coded

Programming device

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals****Form**

Form 99441

**General data**

Protection	IP30
Dimensions H×W×D	70×35×17 mm
Temperature range	0...+60 °C

**Technical Data**

Operating voltage	4.75...5.25 V DC (via the fieldbus device)
Terminating resistor	integrated, switchable
Current consumption	max. 12.5 mA
Transfer rate	max. 12 Mbit/s
Connection	M12×1 mm

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879371360
eClass	27061801

Packaging unit

1