

**CABLE DRUM Ø 355MM**

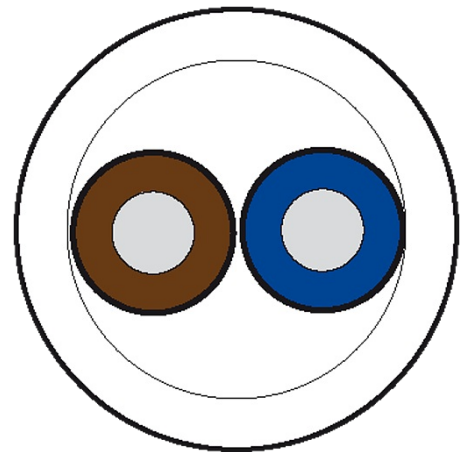
TPE-S-OB 2x0,25 grey 100m

Cable drum (100 m)

TPE-S

2× 0.25 mm<sup>2</sup>

gray

[Link to Product](#)**Illustration**

Product may differ from Image

**Cables**

Cable number	272
No./diameter of wires	2× 0.25 mm <sup>2</sup>
Wire isolation	TPE (bk, bl)
Jacket Color	gray
Material (jacket)	TPE-S
Outer Ø	3.6 mm ±5%
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-50...+125 °C
Temperature range (mobile)	-30...+105 °C
Cable identification	272
Cable weight [g/m]	27,50
Material (wire)	Cu wire, bare
Resistor (core)	max. 76 Ω/km (20 °C)
Single wire Ø (core)	0.1 mm
Construction (core)	32× 0.1 mm (multi-strand wire class 6)
Diameter (core)	2× 0.25 mm <sup>2</sup>
AWG	similar to AWG 24
Material (wire isolation)	TPE-S
Shore hardness (wire isolation)	90 ±5 A
Wire-Ø incl. isolation	1.25 mm ±5%
Stranding combination	2 wires twisted
Shield	no
Material (jacket)	TPE-S

Shore hardness (jacket)	80 ±5 A
Outer-Ø (jacket)	3.6 mm ±5%
Color (jacket)	gray
Bend radius (fixed)	10× outer Ø

**Commercial data**

country of origin	DE
customs tariff number	85444995
EAN	4048879512596
eClass	27062011
Packaging unit	1