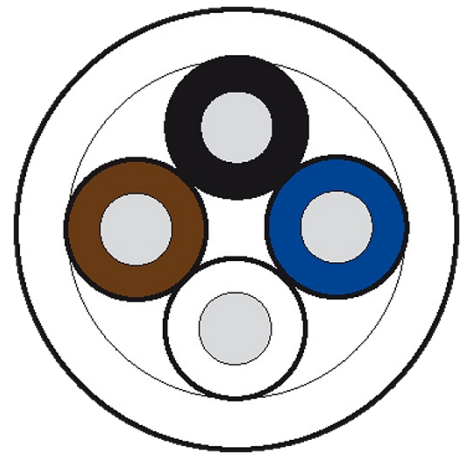


CABLE DRUM Ø 355MM

PUR 4x0.25 shielded black 100m

Cable drum (100 m)
PUR (UL/CSA)
4× 0.25 mm², black
suitable for C-tracks
5 Mio.

[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable identification	714
Approval (cable)	CE conform
Cable weight [g/m]	44,00
Material (wire)	Cu wire, bare
Resistor (core)	max. 76 Ω/km (20 °C)
Single wire Ø (core)	0.1 mm
Construction (core)	32× 0.1 mm (multi-strand wire class 6)
Diameter (core)	4× 0.25 mm ²
AWG	similar to AWG 24
Material (wire isolation)	PVC
Material property (wire isolation)	CFC-, cadmium-, silicone- and lead-free
Shore hardness (wire isolation)	92 ±5 A
Wire-Ø incl. isolation	1.25 mm ±5%
Color/numbering of wires	br, bk, bl, wh
Stranding combination	4 wires twisted
Shield	yes
	min. 85%
Material (jacket)	PUR
Material property (jacket)	CFC-, halogen-, cadmium-, silicone- and lead-free, matt, low-adhesion, machine easy to process, abrasion-resistant, hydrolysis and microbial resistant
Shore hardness (jacket)	85 ±5 A
Outer-Ø (jacket)	5.1 mm ±5%

Color (jacket)	black
chemical resistance	good resistance to oil, gasoline and chemicals
Nominal voltage	300/500 V AC
Test voltage	1500 V AC
Current load capacity	according to DIN VDE 0298-4
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+70 °C
Bend radius (moving)	15× outer Ø
Jacket Color	black

Commercial data

country of origin	IT
customs tariff number	85444995
EAN	4048879340625
eClass	27062011
Packaging unit	1