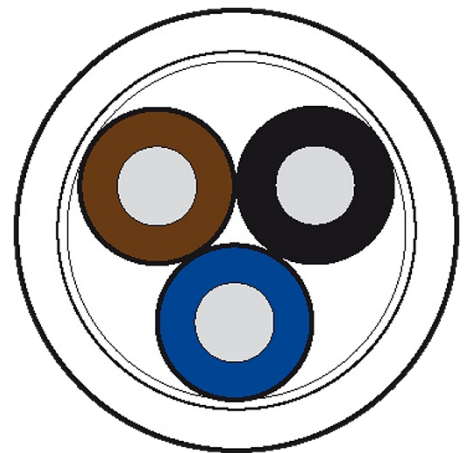


**CABLE DRUM Ø 355MM**

PVC 3X0.34 shielded GRAY, 100m

Cable drum (100 m)

PVC

3× 0.34 mm<sup>2</sup>, grey[Link to Product](#)**Illustration**

Product may differ from Image

**Cables**

Cable number	317
No./diameter of wires	3 × 0.34 mm <sup>2</sup>
Wire isolation	PVC (br, bl, bk)
Jacket Color	gray
Material (jacket)	PVC
Outer Ø	5.9 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	15× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-5...+80 °C
Shield	yes
Color (jacket)	gray
Approval (cable)	CE

**Commercial data**

country of origin	IT
customs tariff number	85444995
EAN	4048879340809
eClass	27062011
Packaging unit	1