


CABLE DRUM Ø 355MM

PUR 3X0.34 shielded GRAY, UL/CSA 100m

Cable drum (100 m)
PUR (UL/CSA)
3× 0.34 mm², grey
shielded

[Link to Product](#)

Illustration

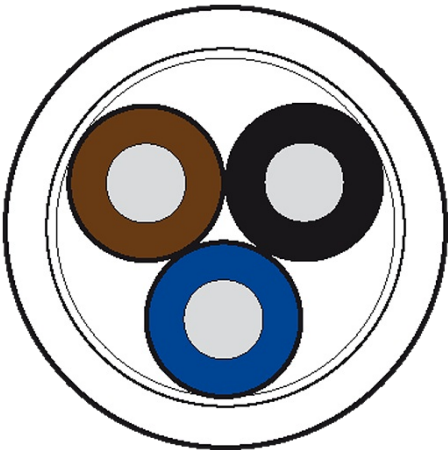

Product may differ from Image

Cables	
Cable number	319
No./diameter of wires	3× 0.34 mm²
Wire isolation	PP (br, bl, bk)
Jacket Color	gray
Material (jacket)	PUR (UL/CSA)
Outer Ø	5.9 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	15× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-20...+80 °C
Shield	yes
Color (jacket)	gray
Approval (cable)	UL (AWM-Style 20233/1992), CSA; CE conform
Diameter (core)	3× 0.34 mm²

Commercial data	
country of origin	DE
customs tariff number	85444995
EAN	4048879405232
eClass	27062011
Packaging unit	1