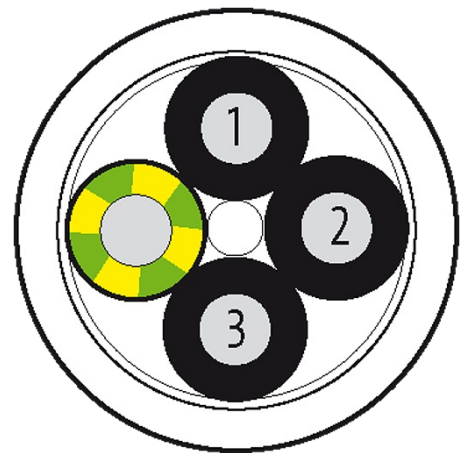


CABLE DRUM Ø 355MM

PVC 4X0.75 shielded GRAY, 100m

Cable drum (100 m)

PVC

4× 0.75 mm², gray[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable identification	499
Approval (cable)	CE conform
Cable weight [g/m]	84,70
Material (wire)	Cu wire, bare
Resistor (core)	max. 26 Ω/km (20 °C)
Single wire Ø (core)	0.2 mm
Construction (core)	24× 0.2 mm (multi-strand wire class 5)
Diameter (core)	4× 0.75 mm ²
AWG	similar to AWG 18
Material (wire isolation)	PVC
Material property (wire isolation)	PVC
Shore hardness (wire isolation)	90 ±5 A
Color/numbering of wires	bk numbered, gnye longitudinally striped
Stranding combination	4 wires twisted
Shield	yes
	min. 85%
Material (jacket)	PVC
Shore hardness (jacket)	80 ±5 A
Outer-Ø (jacket)	6.4 mm ±5%
Color (jacket)	gray
chemical resistance	good resistance to oil, gasoline and chemicals
Nominal voltage	300/300 V AC
Test voltage	2000 V AC
Temperature range (fixed)	-40...+70 °C

Temperature range (mobile)	+5...+70 °C
Bend radius (moving)	15× outer Ø
Jacket Color	gray
Commercial data	
country of origin	DE
customs tariff number	85444995
EAN	4048879443289
eClass	27062011
Packaging unit	1