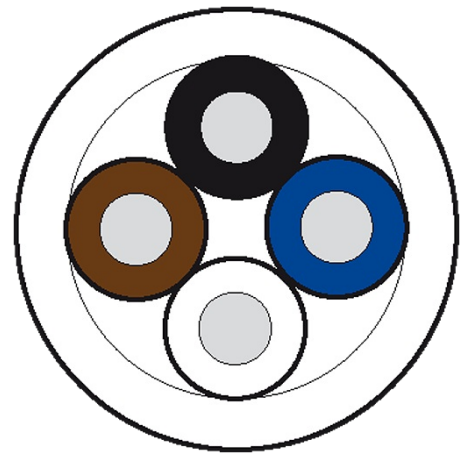


cable drum Ø 500mm

PUR 0.25+1.0 shielded vt drag chain 500m

Cable drum (500 m)
 PUR (UL/CSA), welding spark
 4× 0.34 mm²
 orange
 suitable for C-tracks
 5 Mio.
 Suitable for robots
 ±360°/m

[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable number	815
C-track properties	5 Mio.
Jacket Color	violet
Material (jacket)	PUR
Outer Ø	8.5 mm ±5%
Bend radius (moving)	15× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-30...+70 °C
Cable identification	815
Material (wire)	Cu wire, bare
Diameter (core)	3× 2× 0.25 + 3× 1.0 mm ²
Material (wire isolation)	PO
Wire-Ø incl. isolation	1.3 mm ±5% (0.25 mm ²); 1.7 mm ±5% (1.0 mm ²)
Color/numbering of wires	PO (wh, br) + (ye, gr) + (gr, pk) + rd, bl, gnye
Shield	yes
Material (jacket)	PUR
Outer-Ø (jacket)	8.5 mm ±5%
Color (jacket)	violet
Temperature range (fixed)	-40...+80 °C

Temperature range (mobile)	-30...+70 °C
----------------------------	--------------

Bend radius (fixed)	8× outer Ø
---------------------	------------

Bend radius (moving)	15× outer Ø
----------------------	-------------

Commercial data

country of origin	DE
-------------------	----

customs tariff number	85444995
-----------------------	----------

EAN	4048879403672
-----	---------------

eClass	27062011
--------	----------

Packaging unit	1
----------------	---