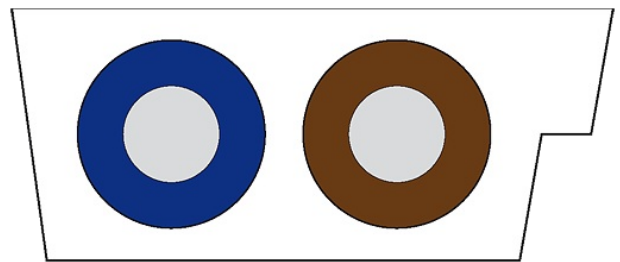


wire bundle MASI

PUR profile cable 2x2.5 bk 100m

PUR (UL/CSA)
suitable for C-tracks
2× 2.5 mm²

[Link to Product](#)**Illustration**

Product may differ from Image

Cables

Cable identification	779
Cable weight [g/m]	83,60
Material (wire)	Cu wire, tin plated
Resistor (core)	max. 8.21 Ω /km (20 °C)
Single wire \varnothing (core)	0.15 mm
Construction (core)	140× 0.15 mm (multi-strand wire class 6)
Diameter (core)	2× 2.5 mm ²
AWG	similar to AWG 14
Material (wire isolation)	PP
Material property (wire isolation)	CFC-, halogen-, cadmium-, silicone- and lead-free
Color/numbering of wires	br, bl
Shield	no
Material (jacket)	PUR
Color (jacket)	black
chemical resistance	good resistance to oil, gasoline and chemicals
Nominal voltage	48 V DC
Current load capacity	to DIN VDE 0298-4
Temperature range (mobile)	-40...+80 °C
Bend radius (fixed)	3× outer- \varnothing
Bend radius (moving)	6× outer \varnothing
Jacket Color	black

Commercial data

country of origin	DE
customs tariff number	85444995
EAN	4048879642316
eClass	27062011
Packaging unit	1