

**cable drum MASI Ø 500mm**

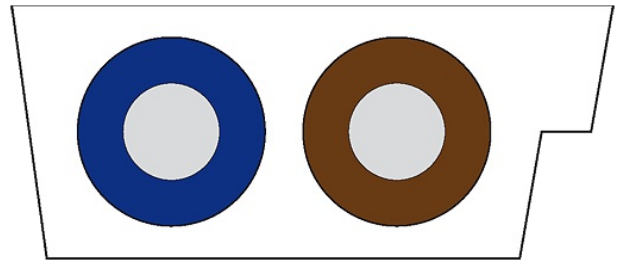
PUR profile cable 2x1.5 ye 1000m

PUR (UL/CSA)

2× 1.5 mm<sup>2</sup>

suitable for C-tracks

5 Mio.

[Link to Product](#)**Illustration**

Product may differ from Image

**Cables**

Cable number	166
No./diameter of wires	2× 1.5 mm <sup>2</sup>
Wire isolation	PP (br, bl)
C-track properties	5 Mio.
Jacket Color	yellow
Material (jacket)	PUR (UL/CSA)
Bend radius (fixed)	5× outer Ø
Bend radius (moving)	7.5× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-20...+80 °C
Color (jacket)	yellow

**Commercial data**

country of origin	DE
customs tariff number	85444993
EAN	4048879565783
eClass	27062011
Packaging unit	1