

T-COUPLER 5 POLEMALE./4 POLEFEMALE M12 SHIELDED V2A

T-coupler

Male straight – females straight

M12 – M12, 5-pole

shielded

Distribution function (NO)

V2A nut/screw

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Form**

Form 42121

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Locking material Stainless steel 1.4305 (V2A)

Commercial data

country of origin DE




customs tariff number 85366990

EAN 4048879313414

eClass 27279220

Packaging unit 1

Sketch

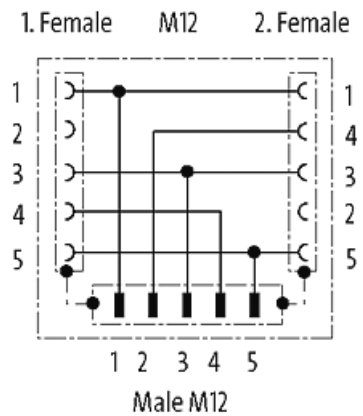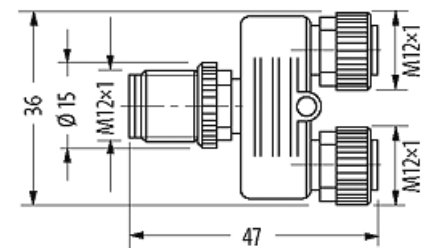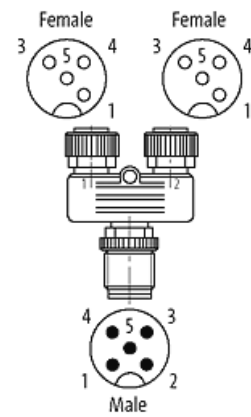

Product may differ from Image