

M12 female 0° with cable V4A

PVC 5x0.34 bk UL/CSA 15m

Female straight

M12, 5-pole

Stainless steel 1.4404 (V4A)


Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Further cable lengths on request.

[Link to Product](#)


Illustration

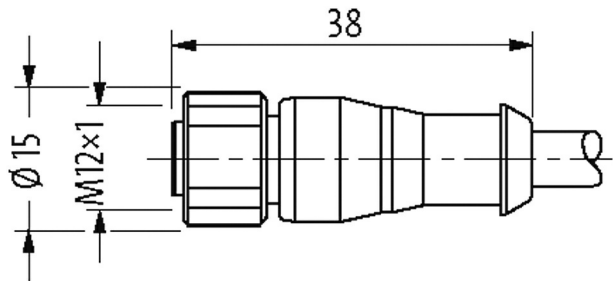

1	↷	brown (+)
2	↷	white (N/C)
4	↷	black (N/O)
3	↷	blue (-)
5	↷	gn/ye (* gray)

(* for cable type 126, 732, 219, 619, 729)

Female

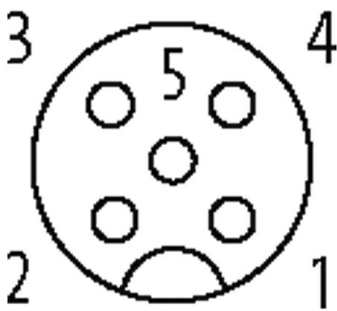

Product may differ from Image