

**T COUPLER M12 LITE MALE / M12 LITE FEMALE 0°**

T-coupler

Male straight – females straight

M12 – M12, 5-pole

Distribution function (NO)

7005 - plastic hexagonal screw (M12 Lite)

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Approvals****Form**

Form 41121

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Locking material Black plastic

Rated surge voltage 1.5 kV

**Commercial data**

country of origin DE




customs tariff number 85366990

EAN 4048879109468

eClass 27279218

Packaging unit 1

**Sketch**

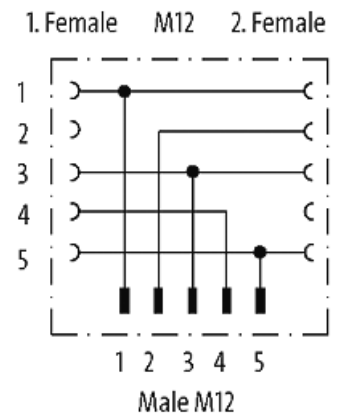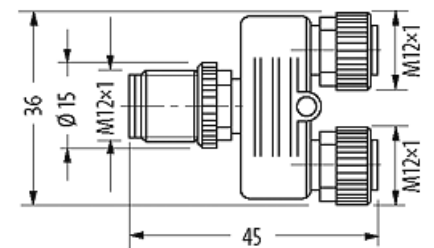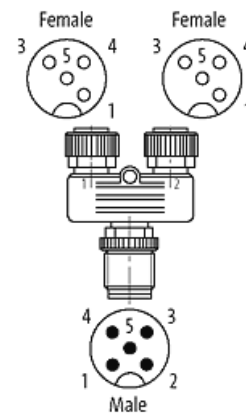

Product may differ from Image