

T COUPLER M12 LITE MALE / M12 LITE FEMALE 0°

T-coupler

Male straight – females straight

M12 – M12, 5-pole

Parallel circuit

7005 - plastic hexagonal screw (M12 Lite)

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**Form**

Form 41141

General data

Temperature range -25...+85 °C

Technical Data

Operating voltage max. 60 V AC/DC

Operating current per contact max. 4 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Locking material Black plastic

Rated surge voltage 1.5 kV

Commercial data

country of origin DE




customs tariff number 85366990

EAN 4048879109451

eClass 27279218

Packaging unit 1

Sketch

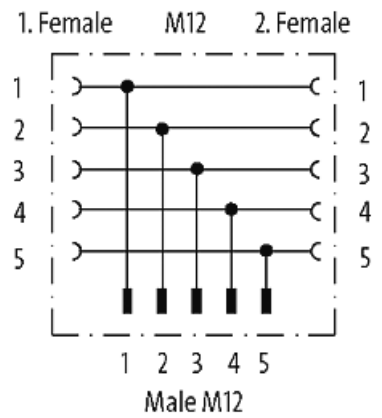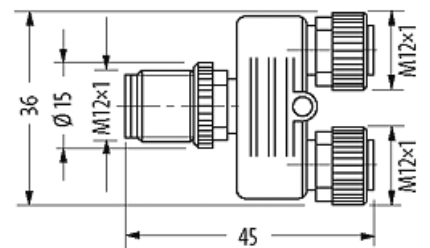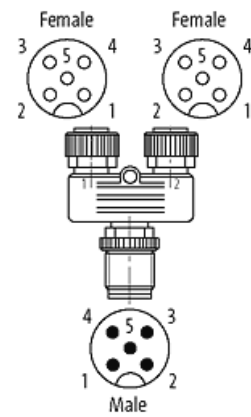

Product may differ from Image