

T COUPLER M12 MALE / M8 FEMALE 0° LITE

T-coupler

Male straight – females straight

M12, 4-pole – M8, 3-pole

Distribution function (NO)


7005 - plastic hexagonal screw (M12/M8 Lite)

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

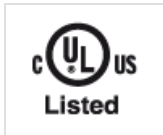Approvals**Form**

Form 41201

General data

Pollution Degree 3

Temperature range -25...+85 °C

Material (gasket) FKM

Technical Data

Operating voltage max. 50 V AC/60 V DC

Operating voltage (only UL listed) max. 30 V AC/DC

Rated surge voltage 1.5 kV

Operating current per contact max. 4 A

Material group IEC 60664-1, category I

Coding A-coded

Locking of ports Screw thread (M8/M12×1 mm) recommended torque 0.4/0.6 Nm, self-securing

Compression gland M8 (SW9), M12 (SW13)

Protection IP67 inserted and tightened (EN 60529)

Locking material PA


Material PUR

Commercial data

country of origin DE

customs tariff number	85366990
EAN	4048879413947
eClass	27279218
Packaging unit	1

Sketch

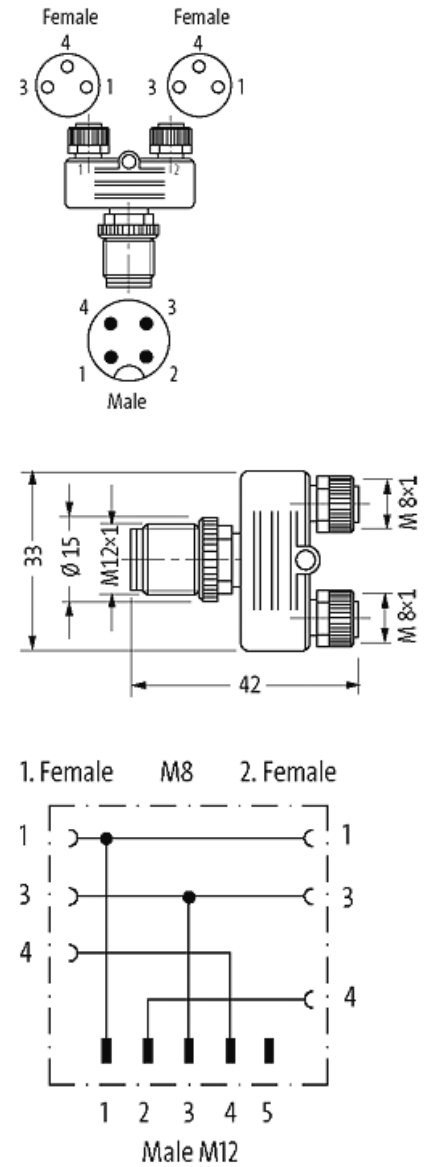

Product may differ from Image