

M12 male receptacle A-cod. front mount F&B

PP-wires 8x0,25 0.5m


F&B

Flange male


M12, 8-pole

Front mounting

Stainless steel 1.4404 (V4A)

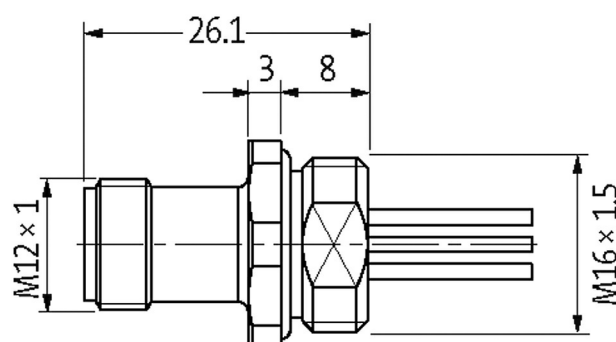[Link to Product](#)**Illustration**

Male

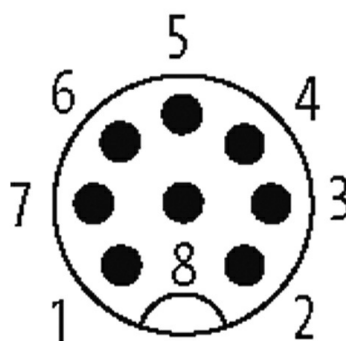

Product may differ from Image

Approvals**Form**

Form 17161

General data

Pollution Degree 3

Temperature range -25...+85 °C

Cables

Cable number 973

No./diameter of wires 8× 0.25 mm²

Wire isolation PUR (wh, br, gn, ye, gr, pk, bl, rd)

Outer Ø 1.25 mm ±5%

Bend radius (fixed) 10× outer Ø

Temperature range (fixed) -40...+90 °C

Temperature range (mobile) -25...+90 °C

Technical Data

Operating voltage max. 30 V AC/DC

Rated surge voltage 0.8 kV

Operating current per contact max. 2 A

No. of poles 8

Material group IEC 60664-1, category I

Coding A-coded

LED display no

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Compression gland M12 (SW14)

Protection IP67 inserted and tightened (EN 60529)

Protection NEMA 3, 4, 6P (UL 50E)

Locking material Stainless steel 1.4404 (V4A)

Commercial data

country of origin DE

customs tariff number 85444290

EAN 4048879363907

eClass 27279220

Packaging unit 1

Sketch

1	■	white
2	■	brown
3	■	green
4	■	yellow
5	■	gray
6	■	pink
7	■	blue
8	■	red

Product may differ from Image