

M12 female 0° with cable

TPE 4x18AWG ye UL/CSA, ITC/PLTC 4m

Female straight

M12, 4-pole


USA

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Further cable lengths on request.


Cable is approved for 600 V

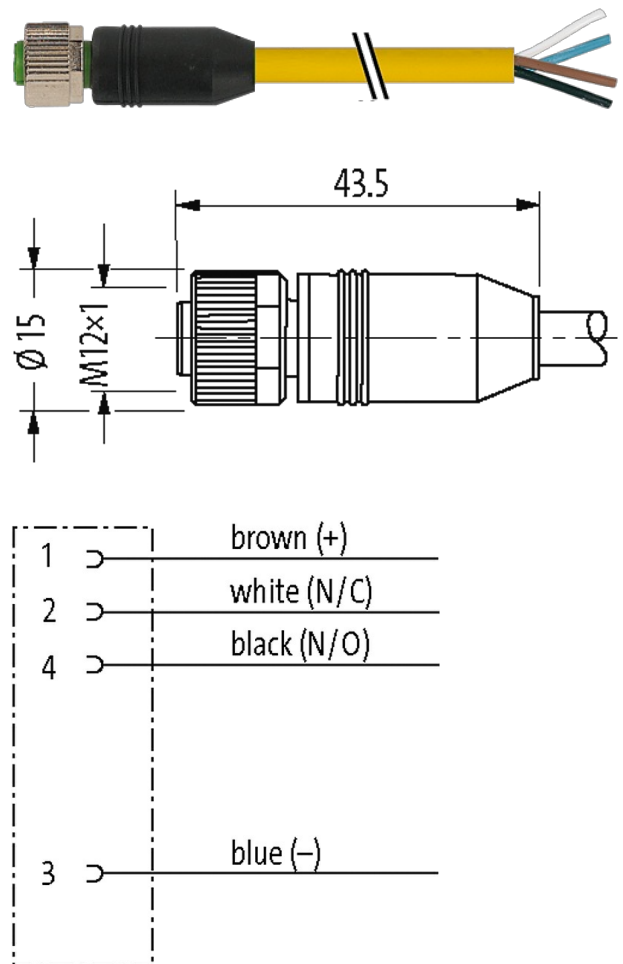Link to Product**Illustration**

Product may differ from Image

Sketch

Female

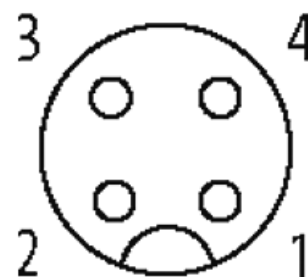

Product may differ from Image