


Rated surge voltage	4.0 kV
Operating current per contact	max. 12 A
No. of poles	3
LED display	no
Locking of ports	Screw thread 7/8" (recommended torque 1.5 Nm) self-securing
Compression gland	7/8" (SW24)
Protection	IP68 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated
Material	PUR


Commercial data

customs tariff number	85444290
EAN	4048879645225
eClass	27279218
Packaging unit	1

Sketch

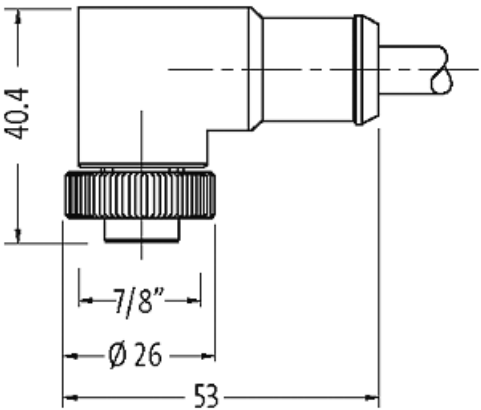

Female

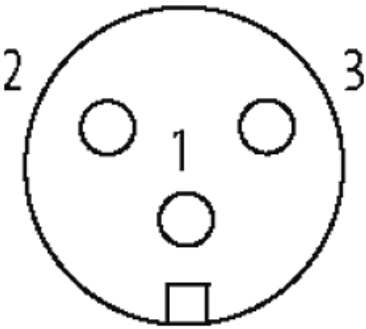

Product may differ from Image