

Mini (7/8) 3 pole, Female 90° w/ Cable,

PUR, UL/CSA, 3x16AWG, black, 10m

Female 90°

7/8" (3-pole)

Power cable


USA

without cable sleeves

Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

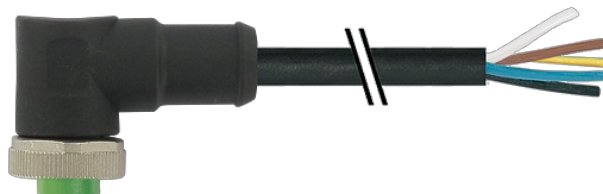[Link to Product](#)**Illustration**

Product may differ from Image

Approvals

* only for products with UL/CSA approved cable

Form

Form A3031

General data

Mounting method	inserted, tightened
Pollution Degree	3
Temperature range	-25...+80 °C, depending on cable quality

Cables

Cable number	UMB
No./diameter of wires	3× 1.5 mm ²
Wire isolation	TPM (br, bl, gnye)
C-track properties	5 Mio.
Jacket Color	black
Material (jacket)	PUR (UL/CSA)
Outer Ø	7.4 mm ±5%
Bend radius (fixed)	7.5× outer Ø
Bend radius (moving)	10× outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-20...+80 °C

Technical Data

Operating voltage	max. 600 V AC/DC
-------------------	------------------

Rated surge voltage 4.0 kV

Operating current per contact max. 12 A

No. of poles 3

LED display no

Locking of ports Screw thread 7/8" (recommended torque 1.5 Nm) self-securing

Compression gland 7/8" (SW24)

Protection IP68 inserted and tightened (EN 60529)

Locking material Zinc die casting, matte nickel plated

Material PUR

Commercial data

country of origin DE


customs tariff number 85444290

EAN 4048879634793


eClass 27279218

Packaging unit 1

Sketch

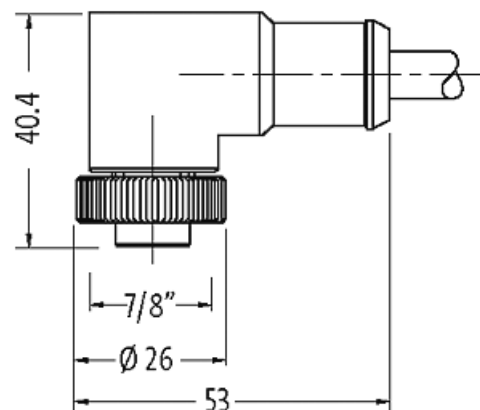

Female

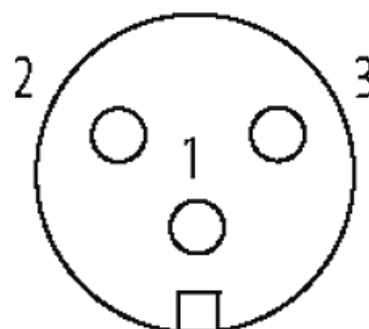

Product may differ from Image