

Mini (7/8) 3 pole, Male (Ext.) 90°/Female 90° ,

PVC, STOOW, 3x16AWG, yellow, 10m

Male 90° – female 90°

7/8" – 7/8", 3-pole

Power cable

USA


Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.


[Link to Product](#)

Illustration

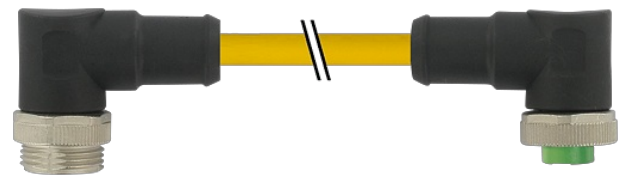

Product may differ from Image

Approvals

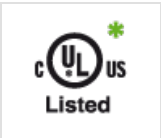

* only for products with UL/CSA approved cable

Form

Form A3A31

General data

Temperature range -25...+80 °C, depending on cable quality

Cables

Cable number	UBB
No./diameter of wires	3× 1.5 mm²
Construction (core)	approx. 3.1 mm
Wire isolation	PVC (bk, gn, wh)
Jacket Color	yellow
Material (jacket)	PVC (UL/CSA)
Outer Ø	10.0 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	15× outer Ø
Temperature range (fixed)	-50...+105 °C
Temperature range (mobile)	-20...+90 °C

Technical Data

Operating voltage	max. 600 V AC/DC
Operating current per contact	max. 12 A
Locking of ports	Screw thread 7/8" (recommended torque 1.5 Nm) self-securing
Compression gland	7/8" (SW24)
Protection	IP68 inserted and tightened (EN 60529)

Locking material	Zinc die casting, matte nickel plated
------------------	---------------------------------------


Material	PUR
----------	-----

Commercial data

customs tariff number	85444290
-----------------------	----------

EAN	4048879644723
-----	---------------

Packaging unit	1
----------------	---

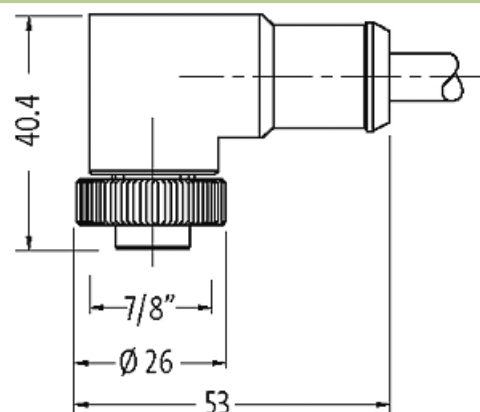Sketch

Product may differ from Image